




Wiremold
2400D Radiused Divided Flat Elbow Fitting
Part No. 2411DFO-FW

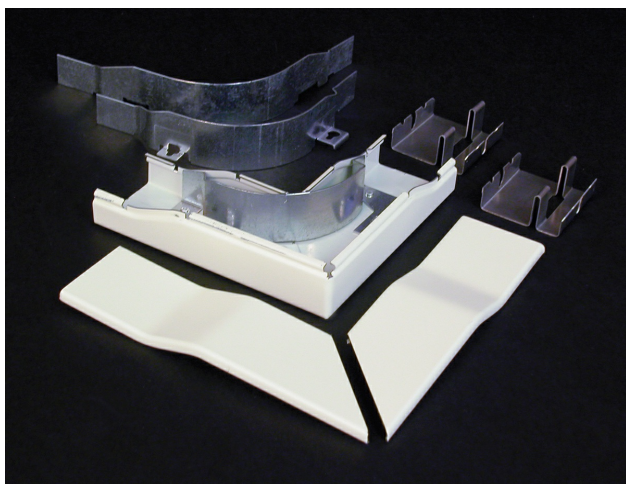

90 degree flat elbow with integral dividers. Provides 2" (51mm) full capacity cable bend radius control for fiber optic and UTP/STP cable installations. Ideal for lay-in or pull-through installations. Two couplings included.

Features & Benefits

90 degree flat elbow with integral dividers. Provides 2" (51mm) full capacity cable bend radius control for fiber optic and UTP/STP cable installations. Ideal for lay-in or pull-through installations. Two couplings included.

Specifications

General Info

Product Line	Wiremold	Color	Fog White
UPC Number	786776132298	Country Of Origin	United States
Application Sector	Commercial, Residential	Standard	cULus Listed Raceway: File E4376 Guide RJBT. Fittings: File E41751 Guide RJPR. Base & Blank Cover: Meets Article 386 of NEC. Meets Section 12-600 of CEC.
Type	Raceway		

Dimensions

Product Weight US	1.27 lb
-------------------	---------

Listing Agencies / 3rd Party Agencies

cULus Listing Number	E41751	cULus Listed	Yes
----------------------	--------	--------------	-----

Additional Information

RoHS Compliant	Yes	Product Environmental Profile	Yes
----------------	-----	-------------------------------	-----

Technical Information

Voltage	600.0 V
---------	---------
