




Wiremold
CableSmart 40N2 Radiused Full Capacity Flat Elbow Fitting
Part No. 40N2F11WH

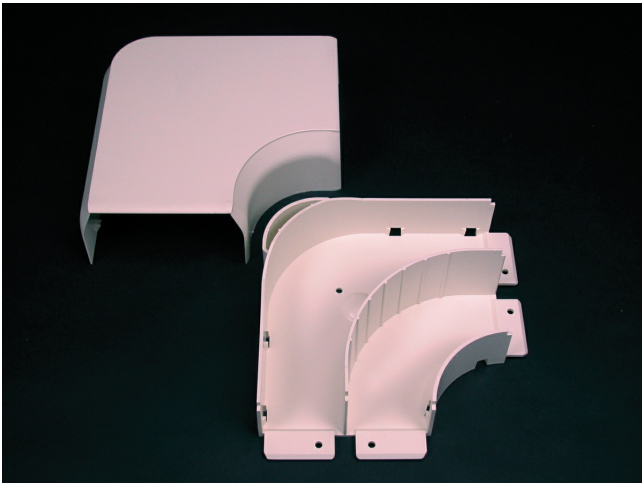

A 90 degree flat corner with integral dividers to provide 2" (51mm) cable bend radius for UTP and fiber optic installations. Ideal for lay-in or pull-through installations.

Features & Benefits

A 90 degree flat corner with integral dividers to provide 2" (51mm) cable bend radius for UTP and fiber optic installations. Ideal for lay-in or pull-through installations.

Specifications

General Info

| | | | |
|-------------------|---|--------------------|------------------------|
| Product Line | Wiremold | UPC Number | 786776136494 |
| Country Of Origin | United States | Application Sector | Residential/Commercial |
| Standard | cULus Listed Raceway: File E90378 Guide RJTX. Complies with Flammability requirements of UL-5A. Fittings: File E90377 Guide RJYT. Meets Article 388 of NEC. UL Listed for up to 600V. Meets Section 12-1600 of CEC. | Type | Raceway |

Dimensions

| | |
|-------------------|----------|
| Product Height US | 6.625 in |
|-------------------|----------|

Listing Agencies / 3rd Party Agencies

| | | | |
|---------------------|--------|--------------|-----|
| cULus ListingNumber | E90377 | cULus Listed | Yes |
|---------------------|--------|--------------|-----|

Buy American Act Compliance

| | |
|-------|-----|
| NAFTA | Yes |
|-------|-----|

Additional Information

| | | | |
|-----------------|-----|-------------------------------|-----|
| RoHS Conformant | Yes | Product Environmental Profile | Yes |
|-----------------|-----|-------------------------------|-----|

Technical Information

| | |
|---------|---------|
| Voltage | 600.0 V |
|---------|---------|