




Wiremold  
CableSmart 40N2 Radiused Full Capacity Internal Elbow Fitting  
Part No. 40N2F17V

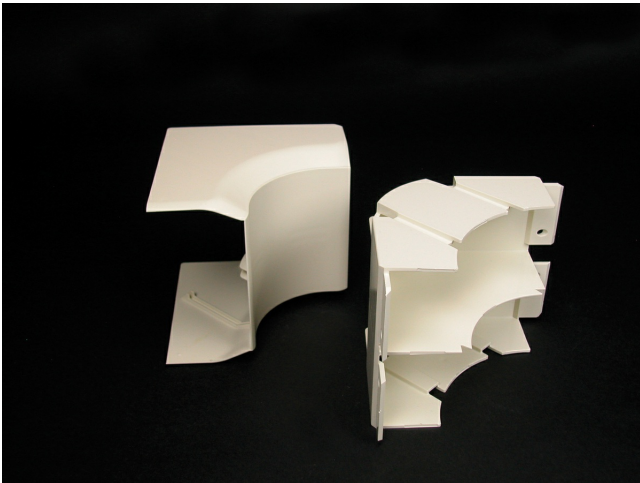

A 90 degree internal corner with integral dividers to provide 2" (51mm) cable bend radius for UTP and fiber optic installations. Each leg is 4 1/2" (114mm). Ideal for lay-in or pull-through installations.

## Features & Benefits

A 90 degree internal corner with integral dividers to provide 2" (51mm) cable bend radius for UTP and fiber optic installations. Each leg is 4 1/2" (114mm). Ideal for lay-in or pull-through installations.

## Specifications

### General Info

Product Line	Wiremold	UPC Number	786776136500
Country Of Origin	United States	Application Sector	Residential/Commercial

Standard	cULus Listed Raceway: File E90378 Guide RJTX. Complies with Flammability requirements of UL-5A. Fittings: File E90377 Guide RJYT. Meets Article 388 of NEC. UL Listed for up to 600V. Meets Section 12-1600 of CEC.	Type	Raceway
----------	---	------	---------

### Dimensions

Product Width US	4.5 in
------------------	--------

### Listing Agencies / 3rd Party Agencies

cULus ListingNumber	E90377	cULus Listed	Yes
---------------------	--------	--------------	-----

### Buy American Act Compliance

---

NAFTA	Yes
-------	-----

---

### Additional Information

---

RoHS Conformant	Yes	Product Environmental Profile	Yes
-----------------	-----	-------------------------------	-----

---

### Technical Information

---

Voltage	600.0 V
---------	---------

---