




Wiremold
CableSmart 40N2 Radiused Full Capacity Internal Elbow Fitting
Part No. 40N2F17WH

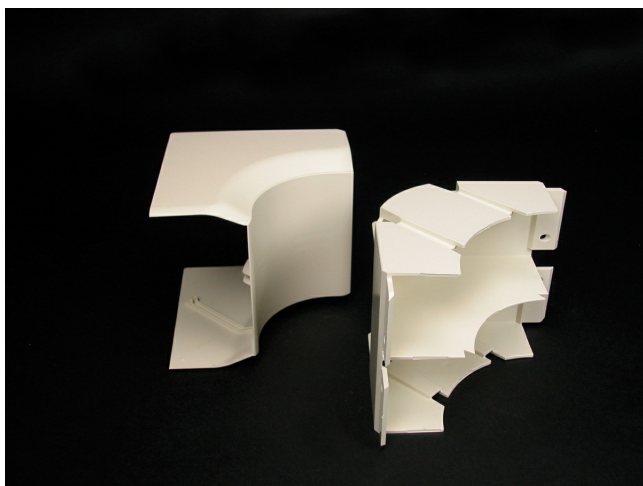

A 90 degree internal corner with integral dividers to provide 2" (51mm) cable bend radius for UTP and fiber optic installations. Each leg is 4 1/2" (114mm). Ideal for lay-in or pull-through installations.

Features & Benefits

A 90 degree internal corner with integral dividers to provide 2" (51mm) cable bend radius for UTP and fiber optic installations. Each leg is 4 1/2" (114mm). Ideal for lay-in or pull-through installations.

Specifications

General Info

| | | | |
|-------------------|---|--------------------|-------------------------|
| Product Line | Wiremold | UPC Number | 786776136517 |
| Country Of Origin | United States | Application Sector | Commercial, Residential |
| Standard | cULus Listed Raceway: File E90378 Guide RJTX. Complies with Flammability requirements of UL-5A. Fittings: File E90377 Guide RJYT. Meets Article 388 of NEC. UL Listed for up to 600V. Meets Section 12-1600 of CEC. | Type | Raceway |

Dimensions

| | | | |
|------------------|--------|-------------------|---------|
| Product Width US | 4.5 in | Product Weight US | 0.46 lb |
|------------------|--------|-------------------|---------|

Listing Agencies / 3rd Party Agencies

| | | | |
|---------------------|--------|--------------|-----|
| cULus ListingNumber | E90377 | cULus Listed | Yes |
|---------------------|--------|--------------|-----|

Trade Programs

| | |
|-------|-----|
| USMCA | Yes |
|-------|-----|

Additional Information

| | | | |
|----------------|-----|-------------------------------|-----|
| RoHS Compliant | Yes | Product Environmental Profile | Yes |
|----------------|-----|-------------------------------|-----|

Technical Information

| | |
|---------|---------|
| Voltage | 600.0 V |
|---------|---------|