




Wiremold
CableSmart 40N2 RADIUS Full Capacity Internal Elbow Fitting
Part No. 40N2F17WH

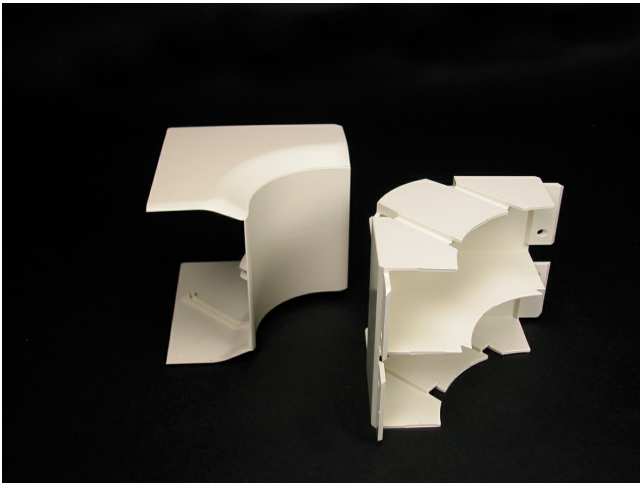

A 90 degree internal corner with integral dividers to provide 2" (51mm) cable bend radius for UTP and fiber optic installations. Each leg is 4 1/2" (114mm). Ideal for lay-in or pull-through installations.

Features & Benefits

A 90 degree internal corner with integral dividers to provide 2" (51mm) cable bend radius for UTP and fiber optic installations. Each leg is 4 1/2" (114mm). Ideal for lay-in or pull-through installations.

Specifications

General Info

Product Line	Wiremold	UPC Number	786776136517
Country Of Origin	United States	Application Sector	Residential/Commercial

Standard	cULus Listed Raceway: File E90378 Guide RJTX. Complies with Flammability requirements of UL-5A. Fittings: File E90377 Guide RJYT. Meets Article 388 of NEC. UL Listed for up to 600V. Meets Section 12-1600 of CEC.	Type	Raceway
----------	---	------	---------

Dimensions

Product Width US	4.5 in
------------------	--------

Listing Agencies / 3rd Party Agencies

cULus ListingNumber	E90377	cULus Listed	Yes
---------------------	--------	--------------	-----

Buy American Act Compliance

NAFTA	Yes
-------	-----

Additional Information

RoHS Conformant	Yes	Product Environmental Profile	Yes
-----------------	-----	-------------------------------	-----

Technical Information

Voltage	600.0 V
---------	---------
