




Pass and Seymour  
15A 120V/125V Combination Single-Pole Toggle Switch and Single Receptacle, Brown  
Part No. 691

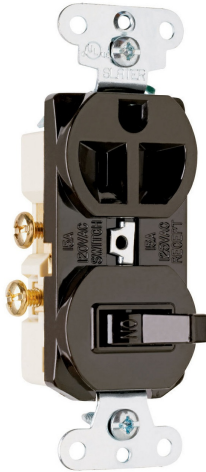

Our standard Pass and Seymour combination switches allow you to add lights to any room in your home without having to add or replace wall boxes.

## Features & Benefits

Easily accessible break-off separate or common feed.

Two devices fit into the space of one.

Tamper-resistant version features dual mechanical shutter system to help prevent insertion of foreign objects.

One-piece heat-treated triple-wipe brass power contacts.

Grounding combination devices meet NEC Requirements.

## Specifications

### General Info

Product Line	Pass & Seymour	Color	Brown
Finish	Matte	Country Of Origin	Mexico
Number of Receptacles	1	Outlet Type	Indoor
Package Quantity	1	Application Sector	Residential/Commercial
Standard	UL20, UL498	Type	Combination, Outlet, Switch

### Dimensions

Product Width US	1.32 in	Product Depth US	0.94 in
Product Height US	4.06 in		

---

## Listing Agencies / 3rd Party Agencies

---

cULus ListingNumber	140597	cULus Listed	Yes
---------------------	--------	--------------	-----

---

## Technical Information

---

Is Tamper-Resistant	No	Contact Configuration	N-0
---------------------	----	-----------------------	-----

---

Operating Cycles	30000	Actuator	Toggle
------------------	-------	----------	--------

---

Connection	Side wire	Contact Rating	120/125 VAC, 15 Amp
------------	-----------	----------------	---------------------

---

Amperage	15 A	Action	SP & Recptacle
----------	------	--------	----------------

---

Number of Poles	Single Pole	Is Weather Resistant	No
-----------------	-------------	----------------------	----

---

Indoor/Outdoor	Indoor	NEMA Configuration Code	5-15R
----------------	--------	-------------------------	-------

---

Mounting Type	Box	Supply Voltage	125 V
---------------	-----	----------------	-------

---

Voltage	120.0 V	Environmental Conditions	Flammability: UL94 V2
---------	---------	--------------------------	-----------------------

---