




**Wiremold**  
**CabinetMate Plug-In Outlet Center Unit / 120V/20A / 77" long / 12 O/L / 6' cord / Computer Grade Surge**  
Part No. 7712BCS20R

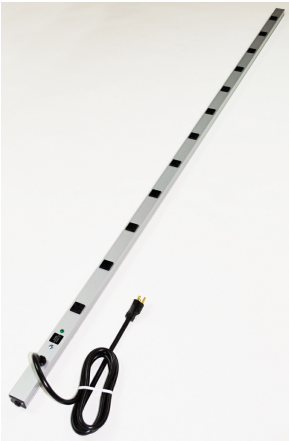

Twelve outlets with t-slots. 6' (1.8m) cord. Length 77" (2m). 20A resettable circuit breaker. Computer grade surge protection, 20 Amps.

## Specifications

### General Info

UPC Number	786776052718	Country Of Origin	Mexico
Product Line	Wiremold	Application Sector	Residential/Commercial
Type	PIOC	Standard	cULus Listed: File E66421, Guide XYBS, XUHT, VZCA

### Listing Agencies / 3rd Party Agencies

cULus Listed	Yes	cULus ListingNumber	E66421
--------------	-----	---------------------	--------

### Buy American Act Compliance

NAFTA	Yes
-------	-----

### Additional Information

RoHS Conformant	Yes
-----------------	-----

### Technical Information

Voltage	600 V	Mounting Type	Spring Clip
Mounting	Yes	Connection	Cord-ended
Class	75	Frequency Rating	+35dB Hz
Phase	Single Stage	Response Time	<1 ns

---

Short Circuit Rating	36,000 Amps [12,000 Amps L-N, 12,000 Amps L-G, 12,000 Amps N-G]	Type of Indicators	Light
----------------------	---	--------------------	-------

---