




Wiremold
861AMDT Series Wood Floor Box Assembly
Part No. 861AMDTAL

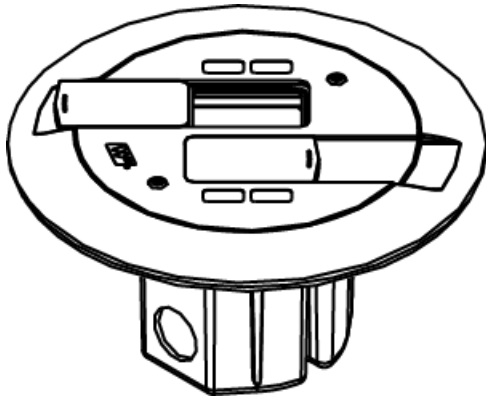

All communication floor boxes accept up to four UTP connectors. Flush poke-thru-style flanges available. Slide covers match painted flange colors. Aluminum and brass flanges shipped with black slide cover. Brass flange also available with nonmetallic brass-color slide holder. Die-cast aluminum construction with three 1/2" trade size knockouts: two on the sides and one on the bottom. 18 cu. in. (295 cu. cm.) capacity. Requires a 4" (102mm) diameter hole and overall floor depth of 1" (25mm). Includes two (2) Ortronics TracJack inserts, two (2) Ortronics Series II adapters and two Wiremold Open System adapters. Assembled with scrub water gasket. For use on tile, wood, or carpet floors. Modular jacks sold separately.

Features & Benefits

All communication floor boxes accept up to four UTP connectors	Flush poke-thru-style flanges available
Slide covers match painted flange colors	Aluminum and brass flanges shipped with black slide cover
Brass flange also available with nonmetallic brass-color slide holder	Includes two (2) Ortronics TracJack inserts, two (2) Ortronics Series II adapters and two Wiremold Open System adapters
Includes two (2) Ortronics TracJack inserts, two (2) Ortronics Series II adapters and two Wiremold Open System adapters	Assembled with scrub water gasket
For use on tile, wood, or carpet floors	Modular jacks sold separately
Die-cast aluminum construction with three 1/2" trade size knockouts: two on the sides and one on the bottom. 18 cu. in. (295 cu. cm.) capacity.	For use on tile, wood, or carpet floors

Specifications

General Info

Product Line	Wiremold	Finish	Brushed
UPC Number	786564013341	Country Of Origin	Mexico
Construction	Assembled	Cover Style	Flush
Number of Knockouts	3	Cover Material	Brushed Aluminum
Application Sector	Commercial	Standard	cULus Listed Metallic Outlet Boxes: File E2961 Guide QCIT Meets Article 314.27(C) of NEC.

Warranty Type	1-Year from Installation or 2-Years from Day of Sale	Type	Floor Box
Dimensions			
Product Weight US	2.0 lb	Cubic Capacity	18 in ³
Knockout Size	1/2 in		
Listing Agencies / 3rd Party Agencies			
cULus ListingNumber	E2961	cULus Listed	Yes
Trade Programs			
USMCA	Yes		
Technical Information			
Floor Type	Raised, Wood	Service Capacity	Single
Minimum Floor Depth	1 in	Box Capacity	1 Gang
Cable Entry	knockout		