




Wiremold  
8801S-FC2 Omnibox Series Fire Classified 1-Gang Floor Box  
Part No. 8801S-FC2

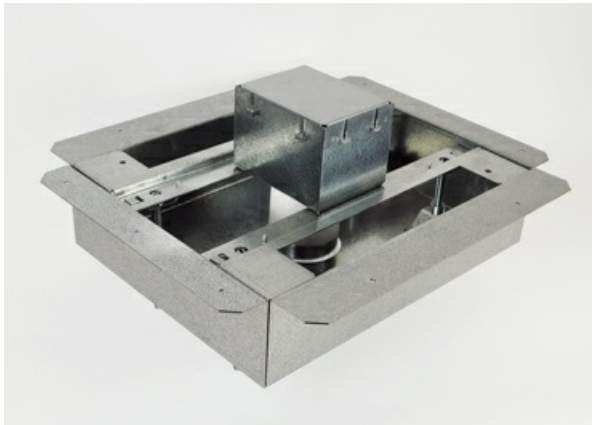

1-Gang Fire Classified Steel Floor Box. Adjustment range over deck of 2" (51mm) minimum to 6-1/2" (165mm) maximum. One 2" (51mm) conduit feed opening. Box Capacity - 53 cubic inches. This box preserves up to a 3-hour fire rating of floors in which it has been installed.

## Features & Benefits

1-Gang Fire Classified Steel Floor Box. Adjustment range over deck of 2" (51mm) minimum to 6-1/2" (165mm) maximum. One 2" (51mm) conduit feed opening. Box Capacity - 53 cubic inches. This box preserves up to a 3-hour fire rating of floors in which it has been installed.

## Specifications

### General Info

Product Line	Wiremold	UPC Number	786776184181
Country Of Origin	United States	Construction	Assembled
Application Sector	Commercial	Standard	cULus Listed Metallic Outlet Boxes: File E2961 Guide QCIT Meets Article 314.27(C) of NEC.
Type	Floor Box		

### Dimensions

Product Width US	11.375 in	Product Depth US	3.5 in
Product Length US	14.5 in	Knockout Size	2 in
Cubic Capacity	53 cu in		

### Listing Agencies / 3rd Party Agencies

cULus ListingNumber	E2961	cULus Listed	Yes
---------------------	-------	--------------	-----

---

Buy American Act Compliance

---

NAFTA	Yes
-------	-----

---

Additional Information

---

RoHS Conformant	Yes
-----------------	-----

---

Technical Information

---

Cable Entry	Conduits
-------------	----------

---