




Wiremold  
8802S-FC12 Omnibox Series Fire Classified 2-Gang Floor Box  
Part No. 8802S-FC12

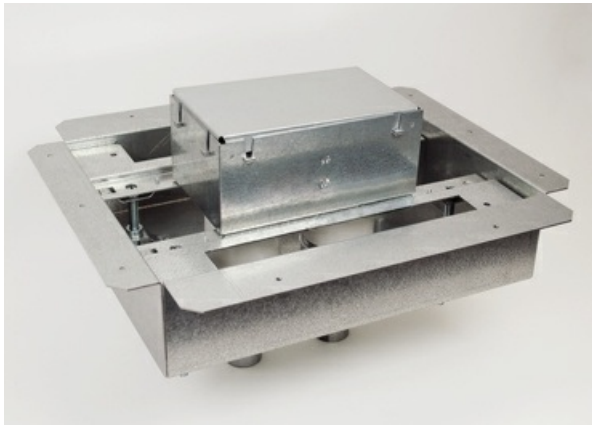

2-Gang Fire Classified Steel Floor Box. Adjustment range over deck of 2" (51mm) minimum to 6-1/2" (165mm) maximum. One 1 1/4" (32mm) and One 2" (51mm) conduit feed openings. Box Capacity - 58.5 cubic inches each gang. This floor box preserves up to a 3-hour fire rating of floors in which it has been installed.

## Features & Benefits

2-Gang Fire Classified Steel Floor Box. Adjustment range over deck of 2" (51mm) minimum to 6-1/2" (165mm) maximum. One 1 1/4" (32mm) and One 2" (51mm) conduit feed openings. Box Capacity - 58.5 cubic inches each gang. This floor box preserves up to a 3-hour fire rating of floors in which it has been installed.

## Specifications

### General Info

Product Line	Wiremold	UPC Number	786776184198
Country Of Origin	United States	Construction	Assembled
Number of Knockouts	1	Application Sector	Commercial
Standard	cULus Listed Metallic Outlet Boxes: File E2961 Guide QCIT Meets Article 314.27(C) of NEC.	Type	Floor Box

### Dimensions

Product Width US	11.375 in	Product Depth US	3.5 in
Product Length US	20.0 in	Cubic Capacity	58.5 cu in

### Listing Agencies / 3rd Party Agencies

cULus Listing Number	E2961	cULus Listed	Yes
----------------------	-------	--------------	-----

### Buy American Act Compliance

---

NAFTA	Yes
-------	-----

---

**Additional Information**

---

RoHS Conformant	Yes
-----------------	-----

---

**Technical Information**

---

Cable Entry	Conduits
-------------	----------

---