




radiant Collection  
radiant® Tamper-Resistant Outlet, Gray  
Part No. 885TRGRY

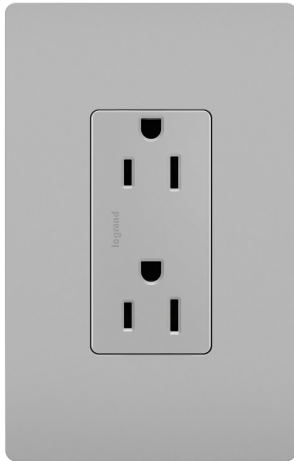

Take a step up from the standard. This tamper-resistant duplex outlet installs easily for the basic power every home needs, while elevating your space with the sleek, clean lines of radiant® for a sophisticated look. Made exclusively for use with screwless Wall Plates from the radiant® Collection, sold separately.

## Features & Benefits

Replaces any standard outlet with ease, in as little as 10 minutes.

Protects children with a patented tamper-resistant shutter system that prevents improper insertion of foreign objects, complete with "invisi-shutters" for an invisible effect.

Complete the look with a sleek, screwless radiant® Wall Plate, and coordinate with other designer switches and outlets available from the radiant® Collection.

Features durable, high-impact resistant thermoplastic construction.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

## Specifications

### General Info

|                       |                         |                   |                                       |
|-----------------------|-------------------------|-------------------|---------------------------------------|
| Product Line          | Pass & Seymour          | Color             | Gray                                  |
| Finish                | Matte                   | Country Of Origin | China                                 |
| Number of Receptacles | 2                       | Outlet Type       | Indoor, Residential, Tamper-Resistant |
| Application Sector    | Residential/Commercial  | Standard          | UL 498                                |
| Warranty Type         | 1-Year Limited Warranty | Type              | Outlet                                |

### Dimensions

|                   |         |                  |        |
|-------------------|---------|------------------|--------|
| Product Width US  | 1.29 in | Product Depth US | 1.0 in |
| Product Height US | 4.2 in  |                  |        |

Listing Agencies / 3rd Party Agencies

cULus Listed                      Yes

Additional Information

Product Environmental Profile    Yes

Technical Information

|                         |             |                          |   |
|-------------------------|-------------|--------------------------|---|
| Is Tamper-Resistant     | Yes         | Amperage                 | 15 A                                    |
| Number of Poles         | Double Pole | Indoor/Outdoor           | Indoor                                  |
| NEMA Configuration Code | 5-15R       | Mounting Type            | Box                                     |
| Voltage                 | 125.0 V     | Environmental Conditions | 95% (relative humidity, non-condensing) |