




Cablofil
CabloPort Extension with FASP 18" Long 8" High [943567]
Part No. 943567

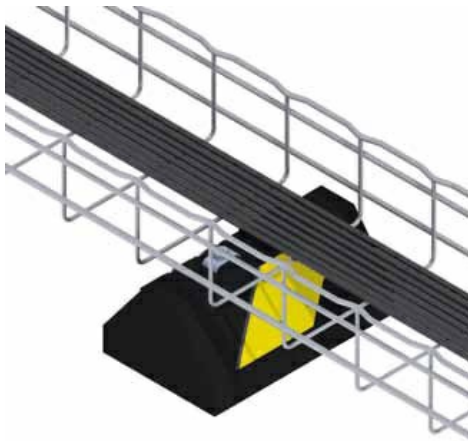

Cablo-Port is a UV and Weather resistant rubber base that creates a cushion between rooftop mounted equipment and sensitive roofing materials. Available in two styles, the Standard style is perfect for smaller loads and tight spaces and the Widebody design provides a broad base to minimize roof pressure and a larger area for glue application. Cablo-Port is also available with a wide variety of pre-mounted support options, including FAS P and Channel.

Features & Benefits

- Height adjustable: For support of cable pathways with varying heights .
- Base includes: two (2) 1/2' Electrozinc threaded rod risers and FAS Profile or channel.
- Install on any roofing material .
- Supports are available in three finishes.
- Standard series maximum load: 150 lbs.
- Widebody design: has maximum load of 500 lbs. Provides 5 times the surface area to minimize roof material pressure, increase load capacity and provide over 120 square in/ft for glue application.

Specifications

General Info

Product Line	Cablofil	Finish	AT
UPC Number	800388019522	Country Of Origin	United States
Application Sector	Commercial	Type	Fasteners

Dimensions

Product Width US	6.0 in	Product Weight US	9.3 lb
Product Volume US	0.5 cu ft	Product Depth US	18.0 in
Product Height US	8.0 in		

Trade Programs

BAA

Yes
