




adorne Collection  
adorne® 15A Dual Tamper-Resistant Plus-Size Outlet, White  
Part No. ARTR153W4

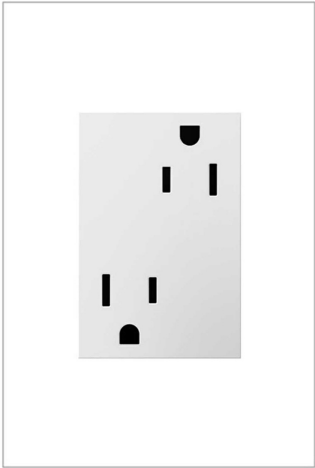

A modern upgrade for style and safety, this tamper-resistant designer outlet from the adorne Collection installs easily for the basic power every home needs, while elevating your space. Made exclusively for use with screwless Wall Plates from the adorne® Collection, sold separately.

### Features & Benefits

- For complete installation, device must be paired with an adorne® screwless Wall Plate (not included). Available in a range of contemporary colors and stunning finishes.

Protects children with a patented tamper-resistant shutter system that prevents improper insertion of foreign objects, complete with "invisi-shutters" for an invisible effect.
- Replaces any standard outlet with ease, in as little as 10 minutes.

More color options available to fit any style, including finishes to match current hardware and lighting trends.

### Specifications

#### General Info

Product Line	Pass & Seymour	Color	White
Finish	Matte	Country Of Origin	China
Number of Receptacles	2	Outlet Type	Indoor, Residential, Tamper-Resistant
Application Sector	Residential	Standard	CULUS
Warranty Type	Limited Lifetime Warranty	Type	Outlet

#### Dimensions

Product Width US	1.77 in	Product Depth US	1.48 in
Product Height US	3.0 in		

#### Technical Information

Phase	Single	Connection	Side and Back Wire
Number of Wires	3	Number of Gangs	1
Amperage	15 A	Number of Poles	Double Pole
Wire Size	14 - 10 AWG	Indoor/Outdoor	Indoor
NEMA Configuration Code	5-15R	Mounting Type	Box
Voltage	125.0 V	Connection Type	Internal Pressure Plates
Environmental Conditions	95% (relative humidity, non-condensing)		