




adorne Collection  
adorne® Touch™ Wi-Fi Ready Master Switch  
Part No. ASTH155RMW1

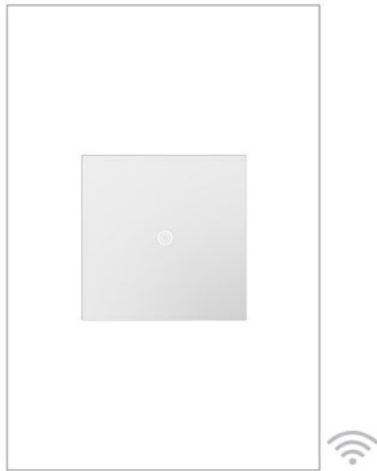

Intuitive touch technology combines with Wi-Fi-Readiness in this sleek lighting control option. The Touch Wi-Fi Ready Master Switch is a programmable light switch that pairs with the adorne Hub to create a smart Wi-Fi Lighting Control System for your home. Turn lights on/off with the touch of a finger, or create custom lighting scenes through the Legrand Lighting Control app for smartphones and tablets. For 3-way, or multi-way applications, use one master device with additional remote devices. Also compatible with the Amazon Alexa and Google Home. Made exclusively for use with screwless Wall Plates from the adorne® Collection, sold separately.

## Features & Benefits

- Installs in 25 minutes or less, fitting into an existing electrical box and wiring directly to the light.
- Compatible with iOS and Android devices for app-based control, simply download the free Legrand Lighting Control app.
- Part of the adorne Wi-Fi Lighting Control System, this device requires the adorne Hub to operate.
- Complete the look with a stunning, screwless adorne® Wall Plate, not included. Available in a range of contemporary colors and finishes. Coordinate with other designer switches & outlets.
- Pair with a Touch Wi-Fi Ready Remote Switch for 3-way control.
- Also compatible with Amazon Alexa and Google Home, and even integrates into advanced home automation systems.
- More color options available to fit any style, including finishes to match current hardware and lighting trends.

## Specifications

### General Info

Color	White	UPC Number	804428065821
Country Of Origin	China	Product Line	Pass & Seymour
Number of Switches	1	Application Sector	Residential
Warranty Type	1-Year Limited Warranty	Standard	UL 508, FCC cULus, RoHS

### Listing Agencies / 3rd Party Agencies

cULus Listed	Yes
--------------	-----

---

## Additional Information

---

RoHS Conformant      Yes

---

## Technical Information

---

Wattage	1800 W	Number of Poles	Single Pole, 3-Way, Multi-Location
Number of Gangs	1	Voltage	120 V
Mounting Type	Box	Supply Voltage	120 V
Connection Type	Internal Pressure Plates	Environmental Conditions	0 to 80 (relative humidity, non-condensing)

---