




adorne Collection  
adorne® 20A Wave® Switch, Magnesium, with Microban®  
Part No. ASWV2032M2

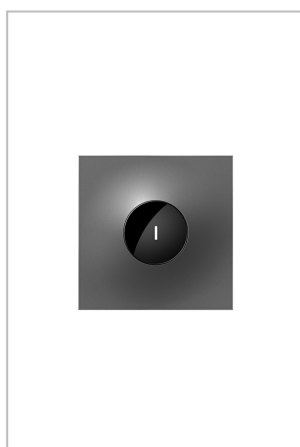

Perfect for turning the lights on or off when your hands are full or messy, especially in entryways or next to the kitchen sink. The 20A Wave Switch features innovative touchless technology that allows you to control lights with a wave of your hand, for a germ- and worry-free option that also adds contemporary style to any space. Use on its own to control a light or fixture from a single location, or pair with a second switch or dimmer to control a single light source from two locations. This switch\* features enduring Microban® antimicrobial technology that works to reduce the growth of bacteria, around the clock, for the lifespan of the product. \*Existing inventory of switches, dimmers and plastic wall plates from the adorne® Collection at some partner locations may not yet include Microban® protection. To confirm that a specific Legrand product is protected with Microban®, check that the exterior of the product packaging includes a green dot or a "Protected with Microban" label. Made exclusively for use with screwless Wall Plates from the adorne® Collection, sold separately. No antimicrobial efficacy claims are being made or are valid with respect to products sold in Canada.

## Features & Benefits

Helps fight the growth of stain and odor-causing bacteria through the invisible and continuous product protection of Microban® antimicrobial technology

Features innovative touchless control for a convenient, germ-free way to turn on lights...all it takes is a simple wave

Made for use in both residential and commercial applications; features durable construction to withstand rigorous cleaning practices

Adjust the internal sensor to respond to movement from 1"-6" from the switch face to fit your space and needs

For complete installation, device must be paired with an adorne® screwless Wall Plate (not included). Available in a range of contemporary colors and stunning finishes.

Installs easily in 15 minutes or less, fitting into an existing electrical box. Usable in both single-pole and 3-way applications

Includes a rating of up to 3/4 HP for adding touchless control to small motors

More color options available to fit any style, including finishes to match current hardware and lighting trends

## Specifications

### General Info

Product Line	Pass & Seymour	Color	Magnesium
Finish	Frosted	UPC Number	785007382495
Country Of Origin	China	Features	Antimicrobial Protection
Switch Type	Wave	Number of Switches	1

Device Front Face Size	Full-Size	Device Backbody Size	Plus-Size
Application Sector	Residential	Warranty Type	Limited Lifetime Warranty
Type	Decorator, Switch		
Dimensions			
Product Width US	1.77 in	Product Depth US	1.71 in
Product Height US	2.66 in		
Listing Agencies / 3rd Party Agencies			
cULus Listed	Yes		
Additional Information			
RoHS Compliant	Yes		
Technical Information			
Connection	Screw Terminals	Amperage	20 A
Number of Poles	Single Pole 3-Way	Wire Size	#14 - #10 AWG
Indoor/Outdoor	Indoor	Connection Type	Internal Pressure Plates