




C2G

Discontinued - 14ft (4.25m) Cat5e Snagless Unshielded (UTP) Ethernet Network Patch Cable - Orange

Part No. CG-00451

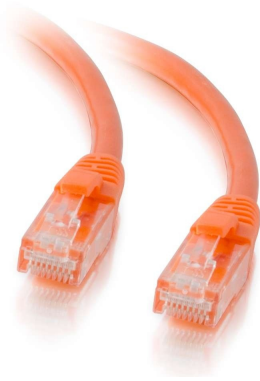

For fast Ethernet networks that require bandwidth-intensive voice, data, or video distribution applications. Meets all Cat5e TIA/EIA standards, and drastically reduces both impedance and structural return loss (SRL). Each of the individual pairs is bonded together to help maintain the twist-spacing throughout the line right up to the termination point. Constructed from high quality copper cable, this design minimizes Near-End Crosstalk (NEXT) levels. The molded, snagless boot prevents unwanted cable snags during installation and provides extra strain relief. Available in a variety of colors to easily color-code your network installation.

Features & Benefits

Snagless design protects clips when plugging and unplugging

Available in 10 colors to color-code a network

Standard RJ45 connectors and unshielded twisted pair wires

Available in lengths up to 150ft

Specifications

General Info

Product Line	C2G	Color	Orange
UPC Number	757120004516	Country Of Origin	Vietnam
Application Sector	Commercial, Industrial, Residential	Warranty Type	Lifetime
Type	Cable		

Dimensions

Cable Length	14 ft
--------------	-------

Technical Information

Jacket Material	PVC (Polyvinyl Chloride)	Wire Gauge	24 AWG
Cable Type	Booted, Ethernet Patch Cable, Snagless, Unshielded (UTP)	Jacket Rating	Standard / Non-Rated
Cable Diameter	5.3 mm	Adapter Rear	RJ-45 Male
Adapter Front	RJ-45 Male		