




On-Q
42-inch Enclosure, No Cover
Part No. EN4280

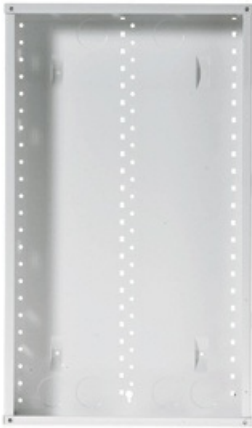

Perfect for larger installations, this 42" enclosure features universal On-Q style mounting holes that are compatible with all bay-style modules. It also includes larger top openings that make pulling wire easier as well as additional knockouts, more s

Features & Benefits

Includes five openings on the top of the enclosure with knockouts

Drywall depth indicators

Flush and surface installation

Mounting tabs provide correct flush-mount position for standard installations

Patented mounting system offers versatile module mounting options

Literature pouch included for dealer information

Includes self-adhesive cable identification table

Made in the USA

Specifications

General Info

| | | | |
|------------------|--|--------------------|---------------|
| Product Line | On-Q | Color | White |
| UPC Number | 804428023203 | Country Of Origin | United States |
| Package Quantity | 1 | Application Sector | Residential |
| Standard | UL (UL985, UL1023, UL1863), cULus, CSA, RoHS | Type | Enclosure |

Listing Agencies / 3rd Party Agencies

| | | | |
|------------|-----|--------------|-----|
| CSA Listed | Yes | cULus Listed | Yes |
|------------|-----|--------------|-----|

Additional Information

| | |
|-----------------|-----|
| RoHS Conformant | Yes |
|-----------------|-----|

Technical Information

| | | | |
|-------------|---|----------------|-------------------|
| Thickness | 0.1 in | Enclosure Type | Traditional |
| Cable Entry | (6) rear knockouts, (3) top knockouts, (2) rectangular knockouts for 1-gang electrical box in | Frame | Cold Rolled Steel |
