




Pass and Seymour
Flexcor® Support Grips Heavy Duty, Double-Eye, Cable Diameter 3.00 - 3.49 in.
Part No. FCHL300UU

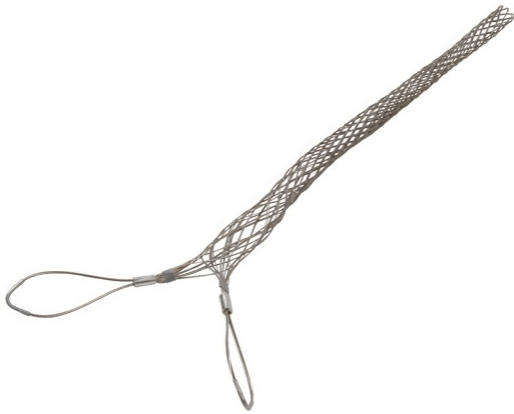

FCHL300UU: Heavy-Duty, Closed Mesh, Double-Eye, Cable Diameter 3.00 - 3.49 inches, Bale Length 10-in, Mesh Length 41-in, Break Strength 10080 lbs.

Features & Benefits

Heavy-duty support grips feature a double weave mesh and are available in a variety of eye styles and cable ranges for supporting electrical and fiber optic cable, metal rods, and tubing.

Support grips are woven of corrosion-resistant tinned-stainless steel wire.

Most Flexcor products have UL and/or CSA approvals. Please contact factory for approval information.

Specifications

General Info

Product Line	Pass & Seymour	UPC Number	785007981506
Country Of Origin	Mexico	Construction	Various Types of Pulling, Support and Strain Relief Grips
Application Sector	Industrial	Standard	UL/CSA Approval (consult factory)

Technical Information

Capacity	Various Cable Diameter Ranges	Cable Size	Cable Dia. Range: 3.000-3.490: Bale Length: 10: Mesh Length: 41
Mounting	Consult the Factory for Mounting Recommendations	Load	Approx. Break Strength: 10,080