




**Pass and Seymour**  
**Stainless Steel Support Grips Standard Duty, Split Lace**  
Part No. FS062USS

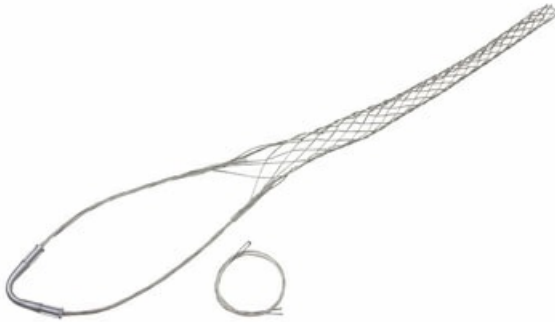

Stainless Steel, Standard-duty, Split lace, single eye. Cable diameter - 0.620-0.740. Bale length - 8-inch, Mesh length - 11-inch, Break strength - 960 lbs.

## Features & Benefits

---

Split lace support grips are designed for loads up to 600 lbs.

They are available in a variety of eye styles and cable ranges for supporting electrical and fiber optic cable, metal rods, and tubing.

Support grips are woven of corrosion-resistant stainless steel wire.

Vertical runs of no more than 100 ft.

Split lace support grips are used when the end of the cable cannot easily be accessed and the support grip is intended for permanent installation.

Most Flexcor products have UL and/or CSA approvals. Please contact factory for approval information.

## Specifications

---

### General Info

---

Product Line	Pass & Seymour	Country Of Origin	Mexico
--------------	----------------	-------------------	--------

---