




Pass and Seymour
Discontinued - Stainless Steel Support Grips Standard Duty, Split Lace
Part No. FS075USS

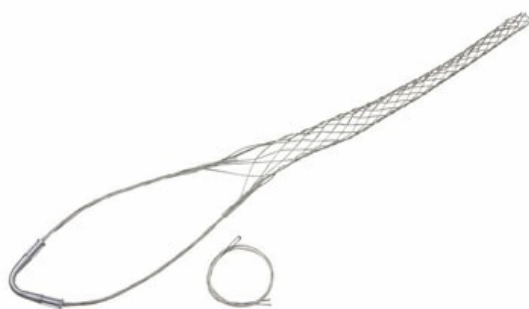

Stainless Steel, Standard-duty, Split lace, Single eye. Cable diameter - 0.750-0.990", Bale length - 8", Mesh length - 14", Break strength - 1,320 lbs.

Features & Benefits

Split lace support grips are designed for loads up to 600 lbs. Vertical runs of no more than 100 ft.

They are available in a variety of eye styles and cable ranges for supporting electrical and fiber optic cable, metal rods, and tubing. Split lace support grips are used when the end of the cable cannot easily be accessed and the support grip is intended for permanent installation.

Support grips are woven of corrosion-resistant stainless steel wire. Most Flexcor products have UL and/or CSA approvals. Please contact factory for approval information.

Specifications

General Info

Product Line	Pass & Seymour	UPC Number	785007141634
--------------	----------------	------------	--------------

Country Of Origin	Mexico
-------------------	--------

Listing Agencies / 3rd Party Agencies

CSA Listed	Yes	CSA File Number	67507
------------	-----	-----------------	-------