




Ortronics 4 Panel High Density Wall Mount Fiber Enclosures Part No. HDSMFC-24PS-00

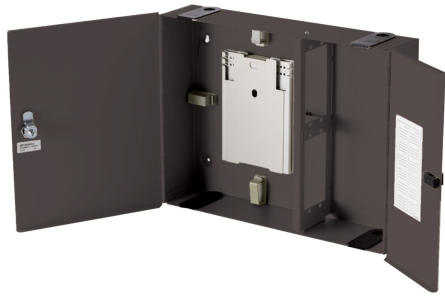

The High Density Wall Mount Fiber Patch/Splice Enclosure system is designed to support high density LAN or POL applications in building networks. The all steel chassis enables reliable protection and management of fiber optic cable patching, splicing, and connecting. The enclosure also enables distribution of backbone cabling to active equipment, switching, or cross/interconnect horizontal area. The 4 panel footprint accommodates up to 96 LC fibers. Each enclosure is compatible with HDFP Adapter Panels, Fiber Splice Trays, and LM4/M4 Pre-terminated or Splice Cassettes.

Features & Benefits

High Density

Accepts 12, 16, or 24 fiber LM4 or M4 pre-terminated or splice cassettes, splice tray, and HDFP adapter panels

Cable Management

Protect and safely route all sensitive fibers with the included cable management system, central strength member bracket, and bend limiters

Steel Construction

Durable & rugged enclosure

Low-Profile Design

Providing unobtrusive protection and management of all enclosed cabling infrastructure

Cable Ingress and Egress

Four ingress or egress points with rubber grommets help to protect and route all connectivity infrastructure.

Lockable

Provides secure environment

Specifications

General Info

| | | | |
|----------|--|--------------|-----------|
| Color | Black | Product Line | Ortronics |
| Included | Rubber grommets, labels, cable strain relief brackets, splice mounting hardware, tie wraps, adhesive hook and loop | Type | Cabinet |

Dimensions

| | | | |
|-------------------|---------|-------------------|---------|
| Product Width US | 16.0 in | Product Height US | 12.0 in |
| Product Weight US | 9.93 lb | Product Depth US | 3.5 in |

Technical Information

| | | | |
|----------|------|---------------|-----------------|
| Mounting | Wall | Compatibility | HDFP, LM4 or M4 |
|----------|------|---------------|-----------------|

| | | | |
|----------|-----------------------------|-------|----|
| Capacity | (4) HDFP, LM4 or M4 modules | Gauge | 18 |
|----------|-----------------------------|-------|----|

| | |
|-------|-------|
| Frame | Steel |
|-------|-------|
