




Wiremold  
2400 15A Isolated Ground Duplex Receptacle Fitting  
Part No. IG2427GA

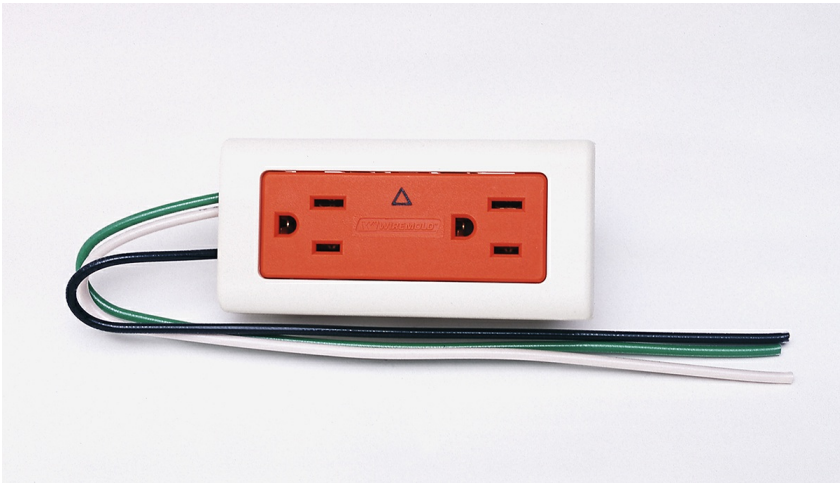

3-Wire 125V NEMA 5-15R orange receptacle. Includes 10 1/2" (267mm) pigtails and inline splice connectors.

Features & Benefits

3-Wire 125V NEMA 5-15R orange receptacle. Includes 10 1/2" (267mm) pigtails and inline splice connectors.

Specifications

General Info

|              |              |                   |               |
|--------------|--------------|-------------------|---------------|
| Product Line | Wiremold     | Color             | Ivory, Orange |
| UPC Number   | 786776155600 | Country Of Origin | United States |

|                    |                         |          |   |
|--------------------|-------------------------|----------|---|
| Application Sector | Commercial, Residential | Standard | cULus Listed Raceway:<br>File E4376 Guide RJBT.<br>Fittings: File E41751<br>Guide RJPR. Base &<br>Blank Cover: Meets<br>Article 386 of NEC. Meets<br>Section 12-600 of CEC. |
|--------------------|-------------------------|----------|---|

|      |         |
|------|---------|
| Type | Raceway |
|------|---------|

Dimensions

|                   |         |                   |           |
|-------------------|---------|-------------------|-----------|
| Product Weight US | 0.25 lb | Product Height US | 2.0625 in |
|-------------------|---------|-------------------|-----------|

Listing Agencies / 3rd Party Agencies

|                     |        |              |     |
|---------------------|--------|--------------|-----|
| cULus ListingNumber | E41751 | cULus Listed | Yes |
|---------------------|--------|--------------|-----|

Additional Information

RoHS Compliant

Yes

Product Environmental Profile

Yes

Technical Information

Voltage

600.0 V