




Wiremold
2400 20A Isolated Ground Duplex Receptacle Fitting
Part No. IG2427GT

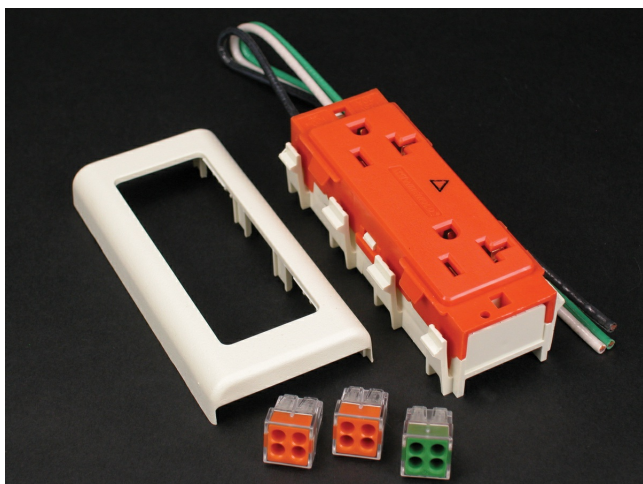

3-Wire 125V NEMA 5-20R orange receptacle. Includes 10 1/2" [267mm] pigtails and inline splice connectors.

Features & Benefits

3-Wire 125V NEMA 5-20R orange receptacle. Includes 10 1/2" [267mm] pigtails and inline splice connectors.

Specifications

General Info

Product Line	Wiremold	Color	Ivory, Orange
UPC Number	786776155617	Country Of Origin	United States

Application Sector	Commercial, Residential	Standard	cULus Listed Raceway: File E4376 Guide RJBT. Fittings: File E41751 Guide RJPR. Base & Blank Cover: Meets Article 386 of NEC. Meets Section 12-600 of CEC.
--------------------	-------------------------	----------	---

Type	Raceway
------	---------

Dimensions

Product Weight US	0.25 lb	Product Height US	2.0625 in
-------------------	---------	-------------------	-----------

Listing Agencies / 3rd Party Agencies

cULus Listing Number	E41751	cULus Listed	Yes
----------------------	--------	--------------	-----

Trade Programs

USMCA	Yes
-------	-----

Additional Information

RoHS Compliant	Yes	Product Environmental Profile	Yes
----------------	-----	-------------------------------	-----

Technical Information

Voltage	600.0 V
---------	---------