




Ortronics
Infinium Ultra M4 Splice Cassette, 12 Single Fiber, LC Duplex, OM4
Part No. M4LCD12-50ES3A1

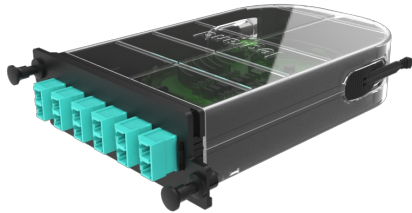

This M4 Splice Cassette enables fast, field termination and provides cable management within the housing. The M4 Splice Cassette is designed for use with Multimode OM4 fiber, houses 12 fibers, and provides LC Duplex ports. This cassette supports fusion splicing of individual fibers, with heat shrinks, pigtail slack and cable slack managed within the cassette. This eliminates the need for individual splice trays or housings, as well as allowing splicing to be done away from the rack housing in a suitable workspace as needed. The design of the cassette allows it to be easily mounted from either the front or the rear of an enclosure or panel. Individual fibers within the cassette may be accessed without disturbing the other fibers in the housing. Tier 3 performance characteristics of this cassette produce typical insertions loss of 0.15dB

Features & Benefits

Flexible Install: Mount from the front or the rear of an enclosure or panel

Clear Top: Enables fast and easy fault identification

Front or Rear Mounting: Simplify installation by mounting from the front or rear of the enclosure panel

Patented Splice Management: Simplify Splicing and fiber management outside of the cassette with the removable fiber splice manager

Installation Convenience: Do all splicing and managing work outside the enclosure

Compact: These Splice cassettes provide a very compact splicing solution

Flexible Install: Mount from the front or rear of an enclosure or panel

Specifications

General Info

Product Line	Ortronics	UPC Number	662875010111
Country Of Origin	China	Application Sector	Commercial
Standard	TIA-568-C.3	Type	Cassette

Dimensions

Product Width US	3.45 in	Product Depth US	4.77 in
Product Height US	1.14 in		

Additional Information

RoHS Conformant

Yes
