




Ortronics
Infinium Core M4 Splice Cassette, 12 Ribbon Fiber, SC Duplex, OM4
Part No. M4SCD12-50ER1A1

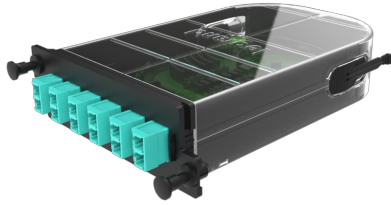

Infinium M4 SC Splice Cassettes enable industry leading performance, fast field termination, and provide cable management within the housing. The Splice Cassettes are designed for use with Single-Mode (OS2) or Multimode (OM4/OM5) Fiber, Houses 12-24. Compatible with Infinium HD-E Rack Mount Fiber Enclosure with M4 Drawer Face.

Features & Benefits

Mounts from either the front or rear of the enclosure or panel Tier 1 performance characteristics for insertion and return loss

Specifications

General Info

Product Line	Ortronics	Color	Aqua
UPC Number	662875027171	Country Of Origin	China
Application Sector	Commercial	Warranty Type	5-Year
Type	Cassette		

Dimensions

Product Width US	4.19 in	Product Depth US	6.15 in
Product Height US	1.24 in		

Technical Information

Fiber Optic Cable Type	OM4	Compatibility	M4
Number of Ports	12	Simplex/Duplex	Duplex
Return Loss	26 dB	Single/Multimode	Multimode
Performance Level/Tier	Infinium Core		