




Ortronics  
**MM20 4-Post Rack - 42 in D adjustable - 7 ftH - 45 RU - White - punched 3/8 in square**  
Part No. MM20742ADJ38-W

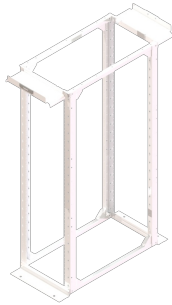

Mighty Mo 20 4-post adjustable racks are allows all 4 mounting rails to be adjusted even after the rack has been fastened to the floor. Availble in depths of 30", 36" & 42" depths in both square hole cage nut styles or threaded rails. Front and rear waterfalls allow for equipment patching and server patching. All styles of Mighty Mo 20 vertical managers can be mounted front or rear and airflow baffles can be mounted to manage the airflow of side breathing equipment.

## Features & Benefits

Large selection of Channel and 4-Post racks	All 4 mounting rails to be adjusted even after the rack has been fastened to the floor
ront and rear waterfalls allow for equipment patching and server patching	Static capacity 2,000 lbs
Threaded hole and square hole punch available on all channel and 4 post racks	Deeper waterfall for increased cable capacity
Rack includes two packages of hook and loop D-style straps and 50 #12-24 cage nuts and screws, do not have to purchase as separate items; money saving	

## Specifications

### General Info

Product Line	Ortronics	Color	White
UPC Number	662875216599	Country Of Origin	United States
Application Sector	Commercial	Type	Rack

### Dimensions

Product Width US	23.75 in	Product Weight US	56.62 lb
Product Depth US	52.0 in	Product Height US	86.0 in

### Additional Information

---

RoHS Conformant	Yes	Product Environmental Profile	Yes
-----------------	-----	-------------------------------	-----

---