




Cablofil
Discontinued - VC-1753-0020-12 G 7"H TROUGH 20'L 12"W
Part No. P013753

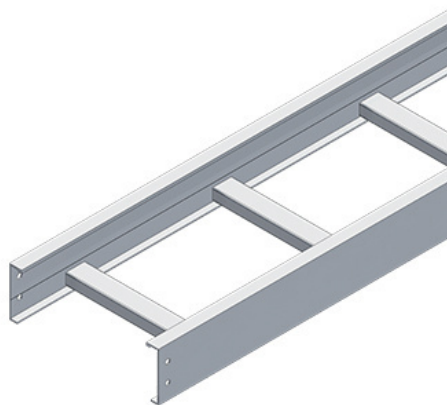

Choose from an extensive selection of metallic ladder tray with a variety of rung and bottom styles to choose from. Rail heights range from 4" to 7" and width sizes are available up to 36".

Features & Benefits

Material: Commercial Quality Steel / ASTM A-1008 / A-1011

Finish: Ho-dip Galvanized after Fabrication / ASTM A-123

Bottom: Ldr: 1" wide + rung SC: Solid Corrugated VC: Vented Corrugated

Construction: Welded

Tray Design: Tray construction and markings are per the latest edition of NEMA Standards Publication VE1, CSA C22.2 No. 126

Tray Grounding Capability: Classified as an equipment grounding conductor per NEC 392.60

Specifications

General Info

Product Line	Cablofil	Finish	Hot Dipped Galvanized after Fabrication
UPC Number	800388276345	Country Of Origin	Mexico
Bottom Type	Vented Corrugated	Application Sector	Commercial, Industrial
Type	Straight Sections		

Dimensions

Product Width US	12.0 in	Product Weight US	139.443 lb
Product Volume US	11.667 cu ft	Product Depth US	240.0 in
Product Height US	7.0 in		

Trade Programs

BAA	Yes
-----	-----

Technical Information

NEMA Load Class	20C
-----------------	-----
