


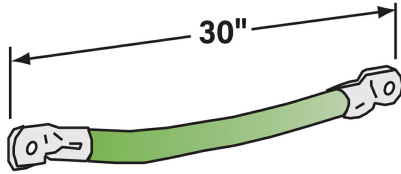

Cablofil
C-A806 #6 200 AMP COPPER BONDING JUMPER
Part No. P087788

Finishes include steel and 316L stainless steel to meet the needs of any application. Rail heights range from 4" to 7".



Features & Benefits

Hardware included

Type 316 stainless steel fasteners are standard on stainless steel systems, but are available as an option on all aluminum and steel systems.

Bonding jumpers are required for all expansion splice plates, adjustable connectors, and tray discontinuities.

Geomet fasteners are standard on aluminum and steel cable tray systems.

Sufficient connector pairs with fasteners are automatically included with each shipment of straight sections and fittings. Extras for field cuts or spares must be ordered separately.

Specifications

General Info

Product Line	Cablofil	Finish	Copper
UPC Number	800388253155	Country Of Origin	Mexico
Application Sector	Commercial, Industrial	Type	Accessories

Dimensions

Product Width US	0.611 in	Product Weight US	0.4 lb
Product Volume US	0.002 cu ft	Product Depth US	16.04 in
Product Height US	0.3 in		

Trade Programs

BAA

Yes
