




Cablofil
09-1954-0030-12 30'L 10"H 12"W G TRAY
Part No. P645375

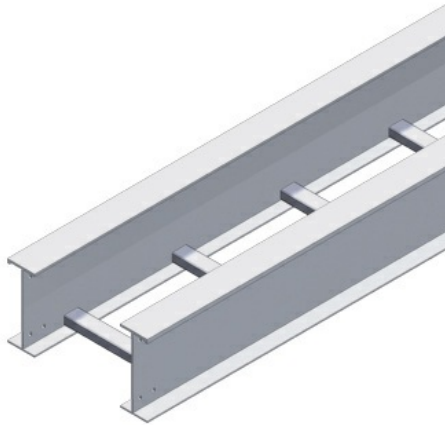

This product line is designed for applications with extremely heavy loads and long spans. Tray systems are available in lengths of 30 and 40 feet to accommodate 30-40 foot support spans.

Features & Benefits

NEMA TRAY TYPE: Two Rail Ladder

NEMA CLASS: 20C+

CSA CLASS: N/A

MATERIAL: Extruded aluminum alloy 6063-T6

BOTTOM: 1-5/8" wide strut rung

FINISH: Plain

CONSTRUCTION: Arc welded

TRAY SERIES: Series 2 (5" tangent)

Specifications

General Info

Product Line	Cablofil	Finish	Hot Dipped Galvanized after Fabrication
UPC Number	800388534810	Country Of Origin	Mexico
Bottom Type	Ladder	Application Sector	Commercial, Industrial
Type	Straight Sections		

Dimensions

Product Weight US	129.08 lb	Rung Spacing	9 in
-------------------	-----------	--------------	------

Trade Programs

BAA	Yes
-----	-----

Technical Information

NEMA Load Class	50C
-----------------	-----
