


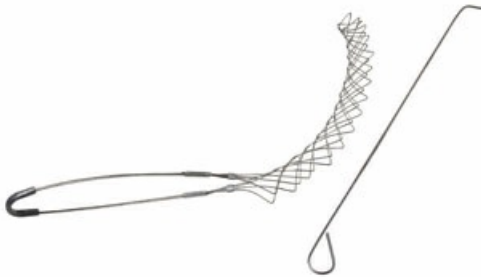

Pass and Seymour
Heavy Duty, Short Length, Rotating Eye, K-Type
Part No. PS1501

Heavy-Duty, Short Length, Rotating Eye, K-Type. Cable Diameter - 1.500-1.990-inch, Mesh Length - 25-inch, Eye Diameter - 1 5/8-inch, 27,200 lbs.



Features & Benefits

K-type pulling grips feature a double weave of galvanized steel for greater strength and added mesh contact with the cable as well as a forged steel compact rotating eye, which can be attached to a swivel.

They are designed to handle longer or heavier pulling jobs such as an installation of underground cables, communication lines and service lines.

Mesh Length: 25: Eye Diameter: 1-5/8

Specifications

General Info

| | | | |
|--------------|---|--------------------|------------|
| Product Line | Pass & Seymour | Country Of Origin | Mexico |
| Construction | Support and Strain Relief Grips, Various Types of Pulling | Application Sector | Industrial |
| Standard | UL/CSA Approval (consult factory) | | |

Technical Information

| | | | |
|---------------------|-------------------------------|---------------------|--|
| Maximum Cable Range | 1.5 in | Minimum Cable Range | 1.99 in |
| Capacity | Various Cable Diameter Ranges | Mounting | Consult the Factory for Mounting Recommendations |
| Load | Approx. Break Strength: 27200 | | |