




Pass and Seymour  
**60A 3 Pole 4 Wire Fusible Mechanical Interlock**  
Part No. PS460FMIR12W

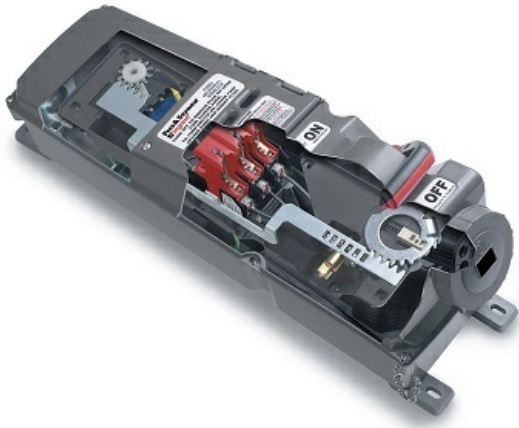

Triple pole, Four wire, Fusible Mechanical Interlock Receptacle. 6 amp, 120/240 vac. 3 HP Standard 10 HP Max.

## Features & Benefits

Top or Bottom feed.

Unit shipped with no holes drilled: a top and bottom feed spot drill is provided for locating hole saw or knockout.

End user decides at installation whether top or bottom feed is appropriate.

No closure plug kits required.

## Specifications

### General Info

Product Line	Pass & Seymour	Color	Gray
UPC Number	785007101188	Country Of Origin	United States

### Listing Agencies / 3rd Party Agencies

cULus Listed	Yes
--------------	-----