




Ortronic

Clarity 6 hinged 48-port panel with lower cable management panel - Cat 6 - 19 in x 8.75 in

Part No. PSD66U48HM

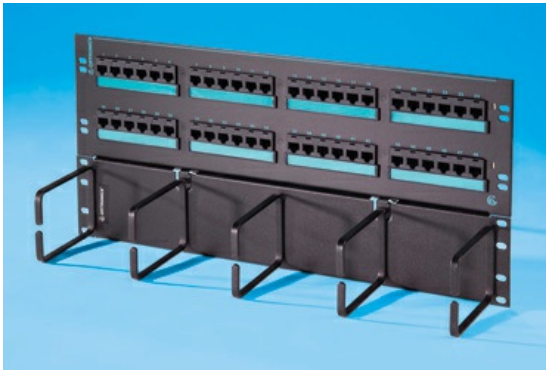

Clarity 6 48-port standard density patch panel with hinged cable management panel is component compliant to TIA/EIA Category 6 performance requirements. It occupies five rack units, and measures 19" x 8.75". Jacks are grouped in six-port modules. It is part of the Clarity 6 link and channel solution that provides significant installed performance headroom.

Features & Benefits

ETL verified to TIA Category 6 component spec: Ensures component performance.

Universally wired 110 termination: Supports T568A and T568B installs.

Supplied rear cable management: Supports good cabling practice.

RoHS compliant: Lead free.

Center tuned to Clarity 6 patch cords: More transparent mated union.

New IDC housing: Handles larger Category 6 conductors.

Standard density design: Provides additional space for cabling.

Specifications

General Info

Product Line	Ortronic	Color	Black
UPC Number	662875482857	Country Of Origin	Mexico
Application Sector	Commercial/Industrial	Type	Panel

Dimensions

Product Width US	19.0 in	Product Depth US	5.0 in
Product Height US	8.75 in		

Additional Information

RoHS Conformant	Yes	Product Has Potential to Contribute to LEED	Yes
-----------------	-----	---	-----