




Ortronics

Clarity 6 hinged 48-port panel with lower cable management panel - Cat 6 - 19 in x 8.75 in

Part No. PSD66U48HM

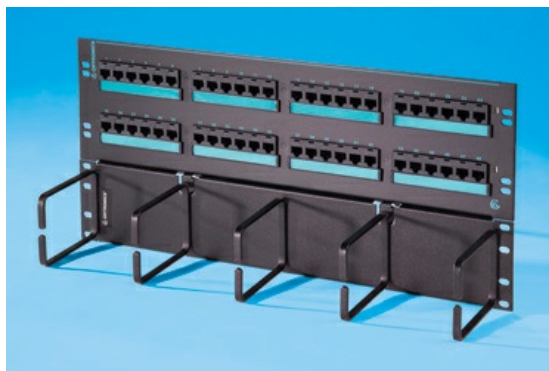

Clarity 6 48-port standard density patch panel with hinged cable management panel is component compliant to TIA/EIA Category 6 performance requirements. It occupies five rack units, and measures 19" x 8.75". Jacks are grouped in six-port modules. It is part of the Clarity 6 link and channel solution that provides significant installed performance headroom.

Features & Benefits

ETL verified to TIA Category 6 component spec: Ensures component performance.

Center tuned to Clarity 6 patch cords: More transparent mated union.

Universally wired 110 termination: Supports T568A and T568B installs.

New IDC housing: Handles larger Category 6 conductors.

Supplied rear cable management: Supports good cabling practice.

Standard density design: Provides additional space for cabling.

RoHS compliant: Lead free.

Specifications

General Info

Product Line	Ortronics	Color	Black
UPC Number	662875482857	Country Of Origin	Mexico
Application Sector	Commercial, Industrial	Warranty Type	5-Year
Type	Panel		

Dimensions

Product Width US	19.0 in	Product Depth US	5.0 in
Product Height US	8.75 in		

Additional Information

RoHS Compliant	Yes	Product Has Potential to Contribute to LEED	Yes
----------------	-----	---	-----

Technical Information

Category Performance Rating	Cat6	Rack Units	5
-----------------------------	------	------------	---

Wire Gauge	22 AWG	Number of Ports	48
Shielded/Unshielded	Unshielded	Connector Type	RJ-45
Wattage	100 W	Voltage	60.0 V