




Pass and Seymour  
PlugTail® Hospital Grade Tamper-Resistant 15A Duplex Self-Test GFCI Receptacle, Ivory  
Part No. PT1597HGTRI

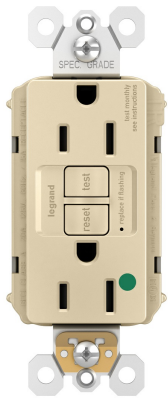

PlugTail® Hospital-Grade Tamper-Resistant 15A Self-Test GFCI Receptacle

## Specifications

### General Info

Product Line	Pass & Seymour	Color	Ivory
Country Of Origin	China	Application Sector	Residential/Commercial
Standard	cULus, UL Listed, FSUL		

### Dimensions

Product Width US	1.72 in	Product Depth US	1.2 in
Product Height US	4.2 in		

### Listing Agencies / 3rd Party Agencies

cULus Listed	Yes
--------------	-----

### Technical Information

Is Tamper-Resistant	Yes	Interrupt Rating	4 A
Frequency Rating	60 Hz	Trip Range	5±1 mA
Connection	Built-in Connector	Amperage	15 A

---

Number of Poles

Double Pole

Voltage

125.0 V

---

Environmental Conditions

95% Humidity, UL 94 V2

---