


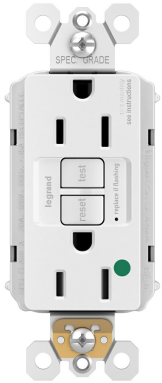

Pass and Seymour  
PlugTail® Hospital Grade 15A Duplex Self-Test GFCI Receptacles with SafeLock® Protection, White  
Part No. PT1597HGW



PlugTail® Hospital-Grade 15A Self-Test GFCI Receptacle

## Specifications

### General Info

|                   |                        |                    |                        |
|-------------------|------------------------|--------------------|------------------------|
| Product Line      | Pass & Seymour         | Color              | White                  |
| Country Of Origin | China                  | Application Sector | Residential/Commercial |
| Standard          | cULus, UL Listed, FSUL |                    |                        |

### Dimensions

|                   |         |                  |        |
|-------------------|---------|------------------|--------|
| Product Width US  | 1.72 in | Product Depth US | 1.2 in |
| Product Height US | 4.2 in  |                  |        |

### Listing Agencies / 3rd Party Agencies

|              |     |
|--------------|-----|
| cULus Listed | Yes |
|--------------|-----|

### Technical Information

|                  |           |                          |                        |
|------------------|-----------|--------------------------|------------------------|
| Interrupt Rating | 4 A       | Frequency Rating         | 60 Hz                  |
| Trip Range       | 4 to 6 mA | Connection               | Built-in Connector     |
| Amperage         | 15 A      | Number of Poles          | Double Pole            |
| Voltage          | 125 V     | Environmental Conditions | 95% Humidity, UL 94 V2 |