




Ortronics
28awg Reduced diameter C6A/10G channel cord Yellow 9FT
Part No. RDC61009-04

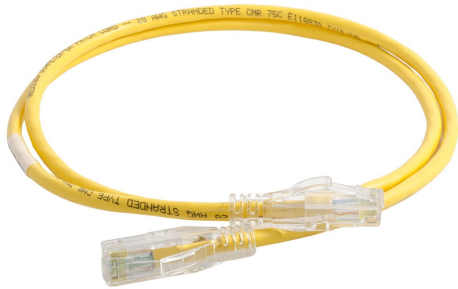

The RDC610 series of modular patch cords offer the reduced diameter of four pairs of 28AWG conductors, providing CAT6A channel performance for high density applications, when looking to reduce congestion or improve airflow through cabling pathways. Common applications include high-density cabling areas such as data centers, end-of-row (EoR) and top-of-rack (ToR) installations or areas such as telecom rooms and equipment rooms.

Features & Benefits

Each cord is 100% factory tested
Ensures every cord shipped support Category 6a channel specifications.

Premium plug designed for reduced OD 28AWG patch cable
Protects performance through the plug termination

Premium 28AWG conductor cordage
Reliable performance and durable cord life.

Improved cable flexibility
Supports simple routing and cable management

Reduced cable diameter
Tighter bend radiuses & occupy less cable management space supporting more airflow

Snagless plug design
Protects plugs when routing through cable managers or pathways.

Backwards compatible to Category 6, and 5e
Supports lower category installations and components.

Specifications

General Info

Product Line	Ortronics	UPC Number	662875854203
Country Of Origin	Mexico	Application Sector	Commercial/Industrial
Standard	FCC	Type	Copper Patch Cord

Additional Information

RoHS Conformant	Yes
-----------------	-----