




Ortronics
28awg Reduced diameter C6A/10G channel cord Blue 15FT
Part No. RDC61015-06

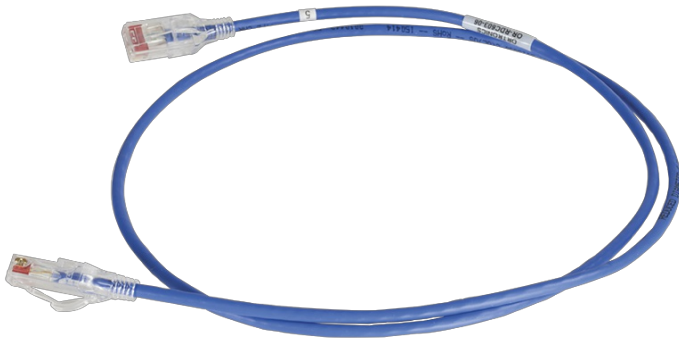

RDC610 Modular Patch Cord, blue, 15', reduced diameter, 28 AWG, cat6a channel four-pair UTP stranded PVC/CM.

Features & Benefits

- Each cord is 100% factory tested: Ensures every cord shipped support Category 6a channel specifications.
- Premium plug designed for reduced OD 28AWG patch cable: Protects performance through the plug termination
- Premium 28AWG conductor cordage: Reliable performance and durable cord life.
- Improved cable flexibility: Supports simple routing and cable management
- Reduced cable diameter: Tighter bend radiuses & occupy less cable management space supporting more airflow
- Snagless plug design: Protects plugs when routing through cable managers or pathways.
- Backwards compatible to Category 6, and 5e: Supports lower category installations and components.

Specifications

General Info

Product Line	Ortronics	UPC Number	662875851844
Country Of Origin	Mexico	Application Sector	Commercial/Industrial
Standard	FCC	Type	Reduced Diameter Patch Cords

Dimensions

Product Length US	15.0 FT
-------------------	---------

Additional Information

RoHS Conformant	Yes	Product Environmental Profile	Yes
-----------------	-----	-------------------------------	-----