




radiant Collection
radiant® Two-Gang Screwless Wall Plate
Part No. RWP262LA

Designed to complement any space, the radiant® Collection features sleek, screwless wall plates for cleaner lines and a sophisticated touch. Pair this two-gang option with your preferred combination of radiant® switches, dimmers, and/or outlets for a completed look that's a step above ordinary.

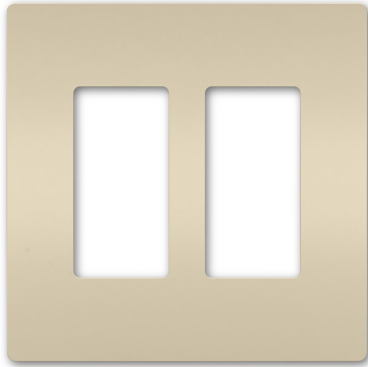

Features & Benefits

radiant screwless wall plates: feature a modern low profile in keeping with today's design trends.

Molded of rugged .065" thick polycarbonate for greater durability.

One-piece subplate: mounts over the device, allowing you to simply snap on the wall plate with ease.

Subplate screws align devices: to ensure proper positioning of the wall plate.

An extra 3/8" width and height than standard size wall plates: for more tolerance in covering ragged sheet rock openings. Opening accommodates all NEMA 26-opening devices.

Specifications

General Info

Color	Light Almond	UPC Number	785007231793
-------	--------------	------------	--------------

Country Of Origin	United States	Product Line	Pass & Seymour
-------------------	---------------	--------------	----------------

Application Sector	Residential/Commercial	Standard	UL514, cULus, CSA Certified
--------------------	------------------------	----------	-----------------------------

Technical Information

Cutout	Decorator	Thickness	0.065 in
--------	-----------	-----------	----------