




radiant Collection
radiant® One-Gang Screwless Wall Plate
Part No. RWP26DBCC6

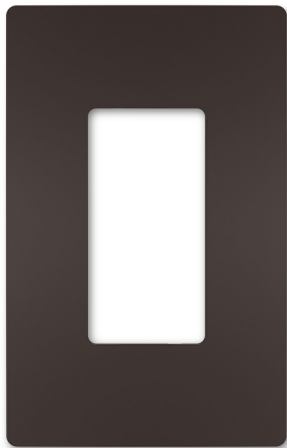

Features & Benefits

Subplate screws align devices: to ensure proper positioning of the wall plate. An extra 3/8" width and height than standard size wall plates: for more tolerance in covering ragged sheet rock openings.

Opening accommodates all NEMA 26-opening devices.

5048

Molded of rugged .065" thick polycarbonate for greater durability.

One-piece subplate: mounts over the device, allowing you to simply snap on the wall plate with ease.

Specifications

General Info

| | | | |
|--------------------|------------------------|--------------|-----------------------------|
| Color | Dark Bronze | UPC Number | 785007320725 |
| Country Of Origin | United States | Product Line | Pass & Seymour |
| Application Sector | Residential/Commercial | Standard | UL514, cULus, CSA Certified |

Dimensions

| | | | |
|------------------|---------|-------------------|---------|
| Product Width US | 4.96 in | Product Height US | 4.94 in |
| Product Depth US | 0.15 in | | |

Technical Information

| | | | |
|-----------------|-----------|---------------|-----------|
| Number of Gangs | 2 | Mounting Type | Screwless |
| Cutout | Decorator | Thickness | 0.065 in |