




Pass and Seymour
Deep Screw Mount Steel Stud Box with Quick/Click
Part No. S122RS

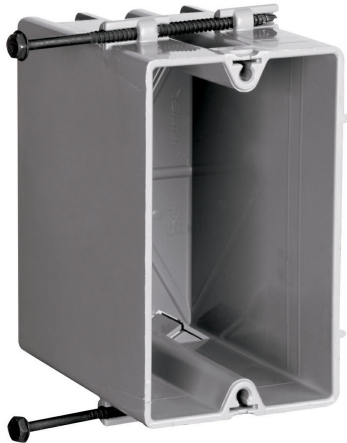

Deep Single-Gang Switch and Outlet Box with Quick/Click and captive combo-head self-tapping mounting screws on each end. Two Quick/Entries on each end. E

Features & Benefits

Quick/Entry feature speeds installation by eliminating need for tools, allows you to push stripped or unstripped non-metallic cable into a single gang plastic box without removing knockouts.

Screws have combination Hex/Phillips washer heads.

Can be used for steel, aluminum, or wood studs.

Locator ribs ensure proper alignment on stud and proper offset depth.

Specially designed drill point rapidly penetrates medium gauge steel studs.

Quick/Click feature on wall boxes offers fast and dependable installation of devices.

Molded of high-impact thermoplastic.

Specifications

General Info

Product Line	Pass & Seymour	Color	Gray
UPC Number	785007651751	Country Of Origin	United States
Features	Deep, Quick Entry, Steel Stud Mount	Installation Location	Wall
Number of Knockouts	4	Application Sector	Commercial, Residential
Standard	Residential/Commercial	Warranty Type	1-Year Limited Warranty
Type	Outlet Box		

Dimensions

Product Width US	2.25 in	Product Depth US	3.375 in
Product Length US	3.75 in	Cubic Capacity	22.5 in³

Additional Information

Product Environmental Profile Yes

Technical Information

Number of Gangs	1	Indoor/Outdoor	Indoor
Cable Entry	Back, Bottom, Top	Box Shape	Rectangular
Mounting Type	Screw Mount		