




Pass and Seymour  
Old Work Switch and Outlet Box with Quick/Click  
Part No. S352W

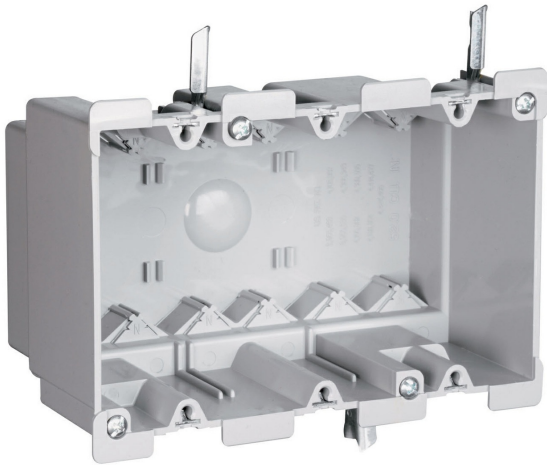

Triple Gang, Old Work Switch and Outlet Box with Swing-Bracket for mounting. Adjusts from 1 1/4-inch down to 1/8-inch. Six Auto/Clamps for Each End. 10 pack.

## Features & Benefits

Quick/Click feature secures devices quickly and easily.

Does not strip when over-torqued.

6: Auto/Clamps on each end eliminate the need for separate cable clamps.

Metal swing bracket for quick mounting in existing walls.

Big 52 cubic inch capacity.

Divider plate (LVDIV1, sold separately) used when installing line and low-voltage devices or multiple 277 volt devices in same box.

Easy installation, rectangular cutout.

Swing bracket adjusts from 1 1/4 inch to 1/8 inch.

Durable, impact-resistant thermoplastic box.

## Specifications

### General Info

Product Line	Pass & Seymour	Color	Gray
UPC Number	785007179149	Country Of Origin	United States
Features	Auto Clamps, Old Work, Quick Entry	Application Sector	Commercial, Residential
Standard	UL Listed	Warranty Type	1-Year Limited Warranty
Type	Switch & Outlet Boxes		

### Dimensions

Product Width US	5.875 in	Product Depth US	3.031 in
------------------	----------	------------------	----------

Product Length US	3.75 in	Cubic Capacity	52 in <sup>3</sup>
-------------------	---------	----------------	--------------------

Listing Agencies / 3rd Party Agencies

cULus Listed	Yes
--------------	-----

Additional Information

RoHS Compliant	Yes	Product Environmental Profile	Yes
----------------	-----	-------------------------------	-----

Technical Information

Number of Gangs	3	Indoor/Outdoor	Indoor
-----------------	---	----------------	--------

Cable Entry	Back, Bottom, Top	Box Shape	Rectangular
-------------	-------------------	-----------	-------------

Mounting Type	Swing Bracket
---------------	---------------