


Smooth Metal Wall Plate, 1gang Decorator, 430 Stainless Steel

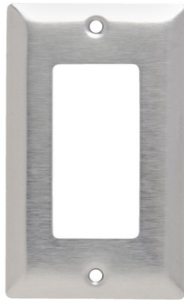

Features & Benefits

Type 430 Stainless Steel, magnetic: .032" nominal thickness.

Brushed finish.

Less corrosion-resistant than Type 302, but ideal for general service in high abuse applications in industrial plants, commercial, and industrial buildings.

Constructed of corrosion-resistant stainless steel, brass, aluminum, chrome, brushed bronze, or galvanized steel.

Standard, Jumbo, and Tandem plates available, as well as special Panel plates up to 5-gangs high and 10-gangs wide.

Packaged in protective film, with finish-matching screws.

Variety of special plated finishes.

Paintable to match plastic plates.

Can be silk-screened or engraved, and custom punched with over 300 opening styles.

Specifications

General Info

UPC Number	785007658101	Country Of Origin	United States
Product Line	Pass & Seymour	Application Sector	Residential/Commercial
Standard	UL 514		

Technical Information

Number of Gangs	1	Cutout	Decorator
Thickness	0.032 in		