




Pass and Seymour
Toggle Switch Openings, Three Gang, 430 Stainless Steel
Part No. SL3

Smooth Metal Wall Plate 3-Gang Toggle 430 Stainless Steel

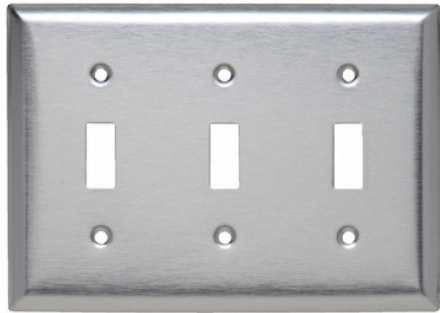

Features & Benefits

Type 430 Stainless Steel, magnetic: .032" nominal thickness.

Brushed finish.

Less corrosion-resistant than Type 302, but ideal for general service in high abuse applications in industrial plants, commercial, and industrial buildings.

Constructed of corrosion-resistant stainless steel, brass, aluminum, chrome, brushed bronze, or galvanized steel.

Standard, Jumbo, and Tandem plates available, as well as special Panel plates up to 5-gangs high and 10-gangs wide.

Packaged in protective film, with finish-matching screws.

Variety of special plated finishes.

Paintable to match plastic plates.

Can be silk-screened or engraved, and custom punched with over 300 opening styles.

For covering patents, see www.legrand.us/patents.

Specifications

General Info

Product Line	Pass & Seymour	Country Of Origin	United States
--------------	----------------	-------------------	---------------

Application Sector	Residential/Commercial
--------------------	------------------------

Dimensions

Product Width US	6.375 in	Product Depth US	0.2 in
------------------	----------	------------------	--------

Product Height US	4.5 in
-------------------	--------

Listing Agencies / 3rd Party Agencies

cULus ListingNumber	143223	cULus Listed	Yes
---------------------	--------	--------------	-----

Technical Information

Cutout	Toggle	Thickness	0.032 in
Number of Gangs	3		
