




Pass and Seymour
Combination Openings, 1 Toggle Switch and 2 Decorator, Three Gang, 302/304 Stainless Steel
Part No. SS1262

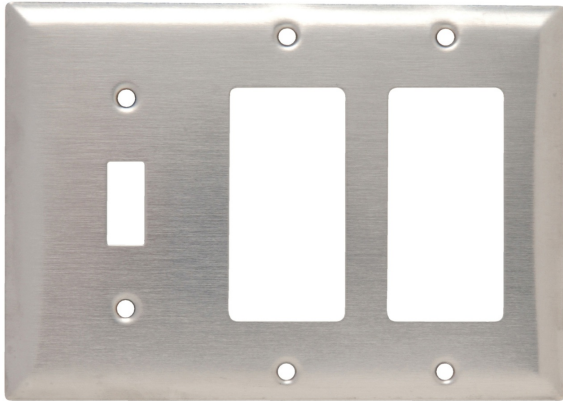

Combination Wall Plate, 1 Toggle Switch and 2 Decorator, 3-Gang, 302/304 Stainless Steel

Features & Benefits

Type 302/304 Stainless Steel, non-magnetic: .032" nominal thickness.

Brushed finish.

This alloy contains 18% chromium and 8% nickel for superior resistance to corrosion.

Recommended for use in food processing plants, dairies, chemical plants, and other industrial, institutional, and commercial applications where corrosive atmospheres exist.

Standard, Jumbo, and Tandem plates available, as well as special Panel plates up to 5-gangs high and 10-gangs wide.

Packaged in protective film, with finish-matching screws.

Variety of special plated finishes.

Paintable to match plastic plates.

Can be silk-screened or engraved, and custom punched with over 300 opening styles.

Specifications

General Info

Product Line	Pass & Seymour	Color	Stainless Steel
Finish	Metallic	UPC Number	785007129892
Country Of Origin	United States	Features	Combination
Wall Plate Type	Combination, Decorator, Toggle Switch	Application Sector	Commercial, Residential
Standard	CSA	Type	Wall Plate

Dimensions

Product Width US	6.375 in	Product Depth US	0.2 in
Product Height US	4.5 in		

Listing Agencies / 3rd Party Agencies

cULus Listed	Yes
--------------	-----

Additional Information

Product Environmental Profile Yes

Technical Information

Cutout	Toggle and Decorator	Thickness	0.032 in
Number of Gangs	3	Wire Size	#14 - #10 AWG
Indoor/Outdoor	Indoor	Orientation	Horizontal