




**Pass and Seymour**  
Decorator Openings, Four Gang, 302/304 Stainless Steel  
Part No. SS264

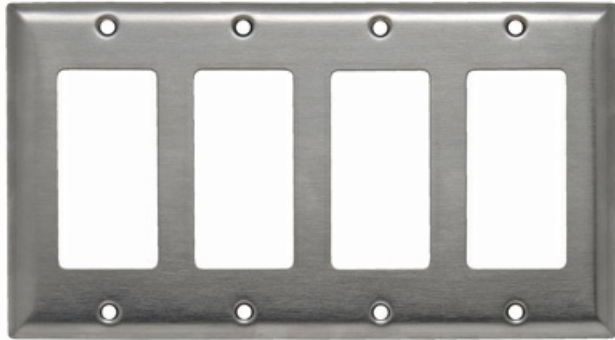

Smooth Metal Wall Plate 4gang Decorator 302/304 Stainless Steel

### Features & Benefits

- Type 302/304 Stainless Steel, non-magnetic: .032" nominal thickness.
- Brushed finish.
- This alloy contains 18% chromium and 8% nickel for superior resistance to corrosion.
- Recommended for use in food processing plants, dairies, chemical plants, and other industrial, institutional, and commercial applications where corrosive atmospheres exist.
- Standard, Jumbo, and Tandem plates available, as well as special Panel plates up to 5-gangs high and 10-gangs wide.
- Packaged in protective film, with finish-matching screws.
- Variety of special plated finishes.
- Paintable to match plastic plates.
- Can be silk-screened or engraved, and custom punched with over 300 opening styles.

### Specifications

#### General Info

UPC Number 785007129564 Country Of Origin United States

Product Line Pass & Seymour Application Sector Residential/Commercial

Standard UL 514

#### Listing Agencies / 3rd Party Agencies

cULus Listed Yes

#### Technical Information

Cutout Decorator Thickness 0.032 in