


Smooth Metal Wall Plate, 8-Gang Decorator, 302/304 Stainless Steel

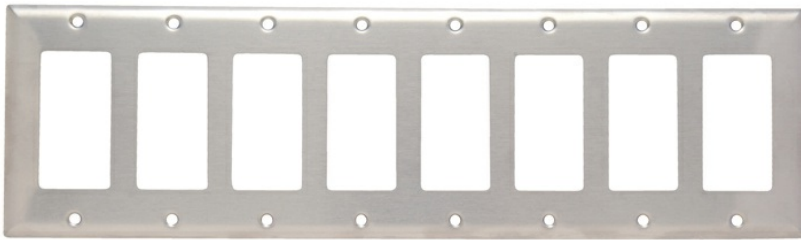

## Features & Benefits

- Type 302/304 Stainless Steel, non-magnetic: .032" nominal thickness. Brushed finish.
- This alloy contains 18% chromium and 8% nickel for superior resistance to corrosion. Recommended for use in food processing plants, dairies, chemical plants, and other industrial, institutional, and commercial applications where corrosive atmospheres exist.
- Standard, Jumbo, and Tandem plates available, as well as special Panel plates up to 5-gangs high and 10-gangs wide. Packaged in protective film, with finish-matching screws.
- Variety of special plated finishes. Paintable to match plastic plates.
- Can be silk-screened or engraved, and custom punched with over 300 opening styles.

## Specifications

### General Info

|                    |                        |                   |               |
|--------------------|------------------------|-------------------|---------------|
| Product Line       | Pass & Seymour         | Country Of Origin | United States |
| Application Sector | Residential/Commercial | Standard          | CSA           |

### Dimensions

|                   |          |                  |        |
|-------------------|----------|------------------|--------|
| Product Width US  | 15.44 in | Product Depth US | 0.2 in |
| Product Height US | 4.5 in   |                  |        |

### Listing Agencies / 3rd Party Agencies

|            |     |              |     |
|------------|-----|--------------|-----|
| CSA Listed | Yes | cULus Listed | Yes |
|------------|-----|--------------|-----|

### Technical Information

|                 |           |           |          |
|-----------------|-----------|-----------|----------|
| Cutout          | Decorator | Thickness | 0.032 in |
| Number of Gangs | 8         |           |          |