




Pass and Seymour
2-Gang 302/304 Stainless Steel Wall Plate, Communication Plate w/ Center OpeningTelephone
Part No. SS741

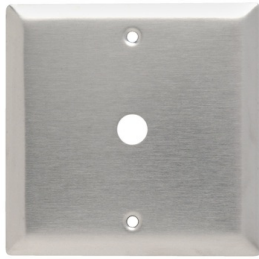

Double gang wall plate with one cente outlet. Box mounted. Smooth 302/304 Stainless Steel.

Features & Benefits

| | |
|---|--|
| Type 302/304 Stainless Steel, non-magnetic: .032" nominal thickness. | Brushed finish. |
| This alloy contains 18% chromium and 8% nickel for superior resistance to corrosion. | Recommended for use in food processing plants, dairies, chemical plants, and other industrial, institutional, and commercial applications where corrosive atmospheres exist. |
| Standard, Jumbo, and Tandem plates available, as well as special Panel plates up to 5-gangs high and 10-gangs wide. | Packaged in protective film, with finish-matching screws. |
| Variety of special plated finishes. | Paintable to match plastic plates. |
| Can be silk-screened or engraved, and custom punched with over 300 opening styles. | |

Specifications

General Info

| | | | |
|-------------------|----------------|--------------------|-------------------------|
| Product Line | Pass & Seymour | Color | Stainless Steel |
| Finish | Metallic | UPC Number | 785007136241 |
| Country Of Origin | United States | Wall Plate Size | Standard Size |
| Wall Plate Type | Telephone | Application Sector | Commercial, Residential |
| Standard | CSA | Warranty Type | 1-Year Limited Warranty |
| Type | Wall Plate | | |

Dimensions

| | | | |
|-------------------|---------|------------------|--------|
| Product Width US | 4.56 in | Product Depth US | 0.2 in |
| Product Height US | 4.5 in | | |

Listing Agencies / 3rd Party Agencies

| | |
|--------------|-----|
| cULus Listed | Yes |
|--------------|-----|

Additional Information

Product Environmental Profile Yes

Technical Information

| | | | |
|----------------|----------|-----------------|-------------|
| Thickness | 0.032 in | Number of Gangs | 2 |
| Indoor/Outdoor | Indoor | Mounting Type | Box Mounted |
| Orientation | Vertical | | |