


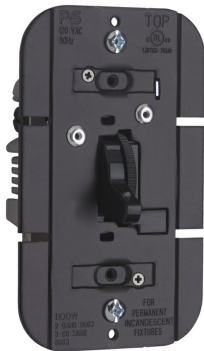

## Pass and Seymour TradeMaster 1100W Incandescent Toggle Dimmer, Black Part No. TD1103PBK

P&S dimmers extend bulb life and can reduce energy consumption by up to 30%. This versatile toggle dimmer provides easy ON/OFF operation and a separate preset allows for convenient, precise dimming control.



### Features & Benefits

Tough, impact-resistant thermoplastic housing.

Uses conventional 3-way wiring when used in conjunction with a 3-way switch.

Lifetime warranty.

No de-rating required in multi-gang operations (700W).

Returns lights to previous level after a power failure.

For covering patents, see [www.legrand.us/patents](http://www.legrand.us/patents).

### Specifications

#### General Info

Color	Black	UPC Number	785007015973
Country Of Origin	China	Product Line	Pass & Seymour
Application Sector	Residential/Commercial	Type	Dimmer
Standard	RoHS		

#### Listing Agencies / 3rd Party Agencies

cULus Listed	Yes
--------------	-----

#### Technical Information

Wattage	1100 W	Voltage	120 V
Connection	Screw Terminals	Frequency Rating	120VAC 60Hz Hz
Load	Incandescent	Environmental Conditions	Humidity: Less than 95% non condensing