




Pass and Seymour  
Discontinued - Trademaster 1100W Incandescent Toggle Dimmer, Ivory | Sub TSD1103PI  
Part No. TD1103PI

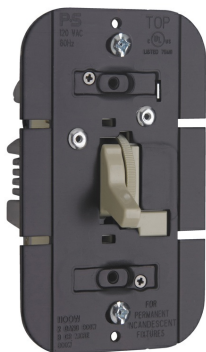

## Features & Benefits

Tough, impact-resistant thermoplastic housing.	No de-rating required in multi-gang operations (700W).
Uses conventional 3-way wiring when used in conjunction with a 3-way switch.	Returns lights to previous level after a power failure.
Lifetime warranty.	For covering patents, see <a href="http://www.legrand.us/patents">www.legrand.us/patents</a> .

## Specifications

### General Info

Product Line	Pass & Seymour	Replaced by Part Number	TSD1103PI
Color	Ivory	Country Of Origin	China
Application Sector	Residential/Commercial	Standard	RoHS
Type	Dimmer		

### Listing Agencies / 3rd Party Agencies

cULus Listed	Yes
--------------	-----

### Technical Information

Frequency Rating	120VAC 60 Hz	Connection	Screw Terminals
Wattage	1100 W	Voltage	120.0 V

---

Load	Incandescent	Environmental Conditions	Humidity: Less than 95% non condensing
------	--------------	--------------------------	---

---