




Pass and Seymour
Discontinued - Trademaster Fluorescent Toggle Dimmer, Ivory | Sub TSDFB83PI
Part No. TDFB83PI

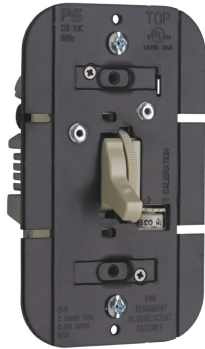

P&S Dimmers save energy and extend bulb life, energy-consumption reductions of up to 30% are possible. The TDFB83P is convenient to operate with a standard ON/OFF toggle switch and separate dimming wheel for precise dimming control. Use specific suffix for color: W- white, BK- black, LA- light almond, I- ivory and no suffix for brown.



Features & Benefits

Tough, impact-resistant thermoplastic housing.

Both single pole and 3-way functionality in one device.

Convenient operation with standard ON/OFF toggle and separate dimming wheel.

Lifetime warranty

For covering patents, see www.legrand.us/patents.

Specifications

General Info

Product Line	Pass & Seymour	Replaced by Part Number	TSDFB83PI
Color	Ivory	Country Of Origin	China
Application Sector	Residential/Commercial	Standard	cULus, RoHS
Type	Dimmer		

Listing Agencies / 3rd Party Agencies

cULus Listed Yes

Technical Information

Frequency Rating 120VAC 60 Hz Connection Screw Terminals

Amperage	8 A	Voltage	120 V
Load	Fluorescent	Environmental Conditions	Humidity: Less than 95% non condensing
